


## SERIES 60



### INJECTION POLYURETHANE WHEELS, POLYAMIDE 6 CENTRE

#### *Wheel description*

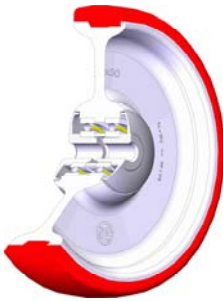

**Tread:** injection polyurethane tread, hardness 55 Shore D; excellent rolling resistance and elasticity, good resistant to wear and to tearing.

**Centre:** polyamide 6.

**Hub** Hub with double shielding ball bearing, co-printed in centre (diam. 80-125 mm). Hub with double shielding ball bearings (diam. 150-200 mm). The bearings are protected from dirt, machining residue and corrosive substances by a glass-fibre reinforced polyamide installation bushing with internal labyrinth seal. Diam. 250 mm: hub with shielded ball bearings with interference assembly in the seats obtained by centre moulding.

Also available with stainless steel ball bearing.