


SERIES 73



**SIGMA ELASTIC RUBBER WHEELS
POLYAMIDE 6 CENTRE
SWIVEL BRACKET WITH STEM TYPE "NL"**

Wheel description

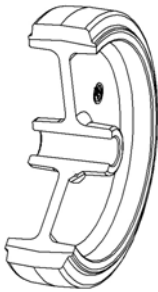


Tread: Sigma Elastic rubber tread; hardness 70+/-3 Shore A.

Centre: polyamide 6.

Hub: The hub is available with plain bore, with roller bearing and with ball bearing.

Bracket description

Standard duty bracket type NL (max. carrying capacity 400 daN)

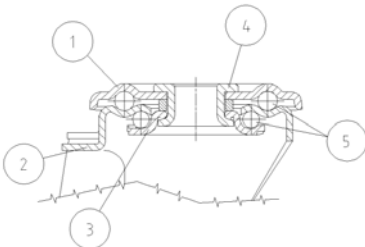

1) **Plate:** electrolytically galvanised steel plate

2) **Fork:** electrolytically galvanised steel plate

3) **Ball Racing Ring:** electrolytically galvanised steel plate

4) **King Pin:** incorporated in top plate and cold riveted

5) **Swivel actions:** double ring of greased balls

Finishing: electrolytic galvanisation

Fitting: stem