


## SERIES 73 AE



**ELASTIC RUBBER WHEELS  
POLYAMIDE 6 CENTRE  
SWIVEL TOP PLATE BRACKET TYPE "NL"**


### Wheel description

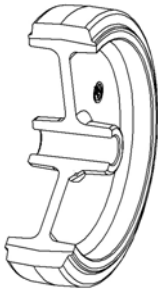

**Tread:** Non-marking blu elastic rubber wheels; hardness 70 Shore A.  
**Centre:** polyamide 6.  
**Hub:** The hub is available with plain bore and with ball bearings.

### Bracket description

**Standard duty bracket type NL (max. carrying capacity 400 daN)**

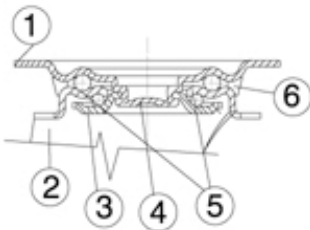

1) **Plate:** electrolytically galvanised steel plate  
2) **Fork:** electrolytically galvanised steel plate  
3) **Ball Racing Ring:** electrolytically galvanised steel plate  
4) **King Pin:** incorporated in top plate and cold riveted  
5) **Swivel actions:** double ring of greased balls  
6) **Dust seal:** orange polyethylene  
**Finishing:** electrolytic galvanisation  
**Fitting:** top plate