


SERIES 73 AE



**ELASTIC RUBBER WHEELS
POLYAMIDE 6 CENTRE
SWIVEL TOP PLATE BRACKET TYPE "NL" WITH BRAKE**


Wheel description

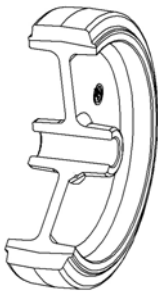

Tread: Non-marking blu elastic rubber wheels; hardness 70 Shore A.
Centre: polyamide 6.
Hub: The hub is available with plain bore and with ball bearings.


Bracket description

Standard duty bracket type NL (max. carrying capacity 400 daN)

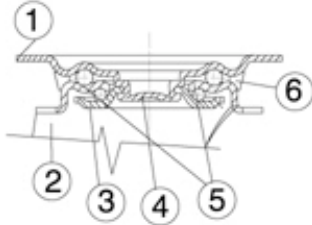

1) **Plate:** electrolytically galvanised steel plate
2) **Fork:** electrolytically galvanised steel plate
3) **Ball Racing Ring:** electrolytically galvanised steel plate
4) **King Pin:** incorporated in top plate and cold riveted
5) **Swivel actions:** double ring of greased balls
6) **Dust seal:** orange polyethylene
Finishing: electrolytic galvanisation
Fitting: top plate

Brake description

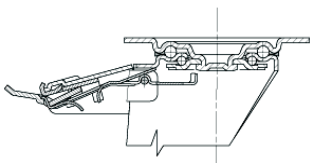

Diameters 80-150 mm



Diameters 150-200 mm

Front-locking brake

This brake fully locks wheel and castor rotation.
Thanks to its optimised dimensions and fold-away pedal, the brake is easy to engage and extremely compact.
The hardened carbon steel spring has very high corrosion resistance.