


## SERIES 78



### INJECTION POLYURETHANE TRANSPALLET ROLLERS, POLYAMIDE 6 CENTRE

#### *Roller description*

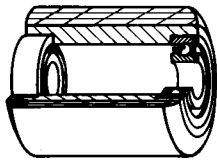

**Tread:** "TR" polyurethane transpallet roller, hardness 95 +/- 3 Shore A, excellent rolling resistance and elasticity, good resistance to wear and to tearing.

**Centre:** polyamide 6 centre.

**Hub:** The housing is obtained by moulding and turning and contains ball bearings series Z. The hub is available also without bearings.