


Adjustable stud barrel tees

Male connector

Thread:
metric fine thread,
straight

Sealed with seal edge

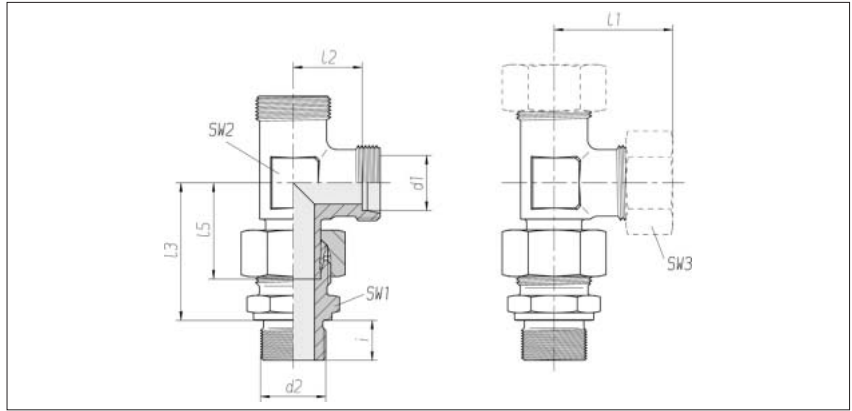

Series	Pressure	d2	SW1	SW2	SW3	L1	L2	L3	L5	i	kg/100 approx.	Order No. Single component	Order No. *
Tube OD d1						approx.							
L 6	PN 315	M 10 x 1	14	12	14	27	12	34.5	26	8	4.8	0 1 62 01 20 07***	0 1 62 00 20 07
L 8	PN 315	M 12 x 1.5	17	12	17	29	14	37.5	27.5	12	6.6	0 1 62 06 20 07	0 1 62 05 20 07
L 10	PN 315	M 14 x 1.5	19	14	19	30	15	40	29	12	8.7	0 1 62 11 20 07	0 1 62 10 20 07
L 12	PN 315	M 16 x 1.5	22	17	22	32	17	42	29.5	12	11.7	0 1 62 16 20 07	0 1 62 15 20 07
L 15	PN 315	M 18 x 1.5	24	19	27	36	21	46	32.5	12	18.4	0 1 62 21 20 07	0 1 62 20 20 07
L 18	PN 315	M 22 x 1.5	27	24	32	40	23.5	50	35.5	14	26.6	0 1 62 26 20 07	0 1 62 25 20 07
L 22	PN 160	M 26 x 1.5	32	27	36	44	27.5	55	38.5	16	28.9	0 1 62 31 20 07	0 1 62 30 20 07
L 28	PN 160	M 33 x 2	41	36	41	47	30.5	59	41.5	18	55.3	0 1 62 36 20 07	0 1 62 35 20 07
L 35	PN 160	M 42 x 2	50	41	50	56	34.5	68.5	51	20	87.0	0 1 62 41 20 07	0 1 62 40 20 07
L 42	PN 160	M 48 x 2	55	50	60	63	40	75	56	22	156.8	0 1 62 46 20 07	0 1 62 45 20 07
S 6	PB 630**	M 12 x 1.5	17	12	17	31	16	40	27	12	8.4	0 1 62 51 20 07	0 1 62 50 20 07
S 8	PB 630**	M 14 x 1.5	19	14	19	32	17	42.5	27.5	12	13.9	0 1 62 56 20 07	0 1 62 55 20 07
S 10	PB 630**	M 16 x 1.5	22	17	22	34	17.5	45	30	12	15.4	0 1 62 61 20 07	0 1 62 60 20 07
S 12	PB 630**	M 18 x 1.5	24	17	24	38	21.5	48	31	12	20.2	0 1 62 66 20 07	0 1 62 65 20 07
S 14	PB 630**	M 20 x 1.5	27	19	27	40	22	54	35	14	25.7	0 1 62 71 20 07	0 1 62 70 20 07
S 16	PB 400	M 22 x 1.5	27	24	30	43	24.5	55	36.5	14	31.5	0 1 62 76 20 07	0 1 62 75 20 07
S 20	PB 400	M 27 x 2	32	27	36	48	26.5	65	44.5	16	78.2	0 1 62 81 20 07	0 1 62 80 20 07
S 25	PB 400	M 33 x 2	41	36	46	54	30	73	50	18	70.7	0 1 62 86 20 07	0 1 62 85 20 07
S 30	PB 250	M 42 x 2	50	41	50	62	35.5	78.5	55	20	126.0	0 1 62 91 20 07	0 1 62 90 20 07
S 38	PB 250	M 48 x 2	55	50	60	72	41	89	63	22	186.7	0 1 62 96 20 07	0 1 62 95 20 07

* With union nut and 2S cutting ring

** Safety factor 2.0

*** Sample product code, see: EVL06LMOMD