


Adjustable stud couplings

Male connector

Component parts
Tube socket pre-assembled

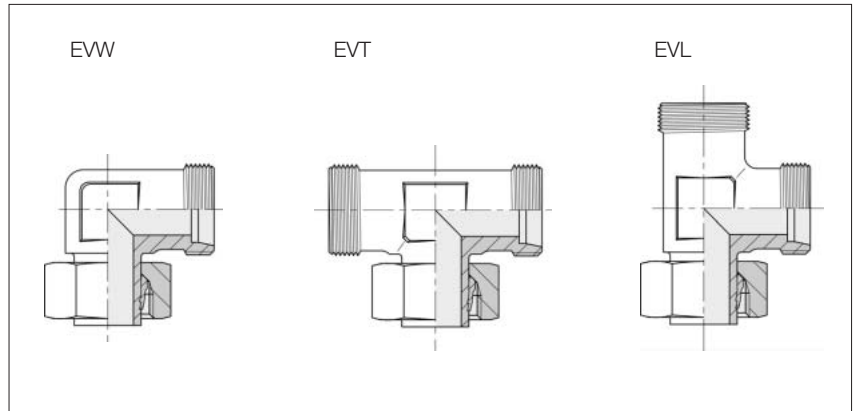

Series	Pressure	kg/100 approx.	Order No.	kg/100 approx.	Order No.	kg/100 approx.	Order No.
Tube OD			EVW		EVT		EVL
d1							
L 6	PN 315	2.8	0 1 58 03 20 07*	3.8	0 1 60 03 20 07*	3.4	0 1 62 03 20 07*
L 8	PN 315	3.8	0 1 58 08 20 07	4.8	0 1 60 08 20 07	4.7	0 1 62 08 20 07
L 10	PN 315	5.0	0 1 58 13 20 07	6.0	0 1 60 13 20 07	6.0	0 1 62 13 20 07
L 12	PN 315	6.6	0 1 58 18 20 07	7.9	0 1 60 18 20 07	7.9	0 1 62 18 20 07
L 15	PN 315	11.5	0 1 58 23 20 07	14.2	0 1 60 23 20 07	13.7	0 1 62 23 20 07
L 18	PN 315	17.8	0 1 58 28 20 07	21.1	0 1 60 28 20 07	20.8	0 1 62 28 20 07
L 22	PN 160	23.5	0 1 58 33 20 07	27.8	0 1 60 33 20 07	27.2	0 1 62 33 20 07
L 28	PN 160	34.1	0 1 58 38 20 07	38.6	0 1 60 38 20 07	39.1	0 1 62 38 20 07
L 35	PN 160	57.7	0 1 58 43 20 07	66.0	0 1 60 43 20 07	66.1	0 1 62 43 20 07
L 42	PN 160	87.2	0 1 58 48 20 07	101.8	0 1 60 48 20 07	100.6	0 1 62 48 20 07
S 6	PN 630	4.4	0 1 58 53 20 07	5.8	0 1 60 53 20 07	5.6	0 1 62 53 20 07
S 8	PN 630	5.9	0 1 58 58 20 07	7.6	0 1 60 58 20 07	7.8	0 1 62 58 20 07
S 10	PN 630	8.3	0 1 58 63 20 07	10.3	0 1 60 63 20 07	10.3	0 1 62 63 20 07
S 12	PN 630	10.5	0 1 58 68 20 07	13.5	0 1 60 68 20 07	13.4	0 1 62 68 20 07
S 14	PN 630	14.6	0 1 58 73 20 07	17.9	0 1 60 73 20 07	17.7	0 1 62 73 20 07
S 16	PN 400	19.9	0 1 58 78 20 07	24.1	0 1 60 78 20 07	22.5	0 1 62 78 20 07
S 20	PN 400	29.4	0 1 58 83 20 07	34.8	0 1 60 83 20 07	34.8	0 1 62 83 20 07
S 25	PN 400	54.1	0 1 58 88 20 07	63.0	0 1 60 88 20 07	63.5	0 1 62 88 20 07
S 30	PN 400	76.2	0 1 58 93 20 07	90.8	0 1 60 93 20 07	91.4	0 1 62 93 20 07
S 38	PN 315	118.9	0 1 58 98 20 07	141.7	0 1 60 98 20 07	141.7	0 1 62 98 20 07

* Sample product code, see:
EWW06LOMD
EVT06LOMD
EVL06LOMD