


## Rückschlagventile

beidseitig zölliges  
Innengewinde

Öffnungsdruck 1 bar  
(Normalausführung)

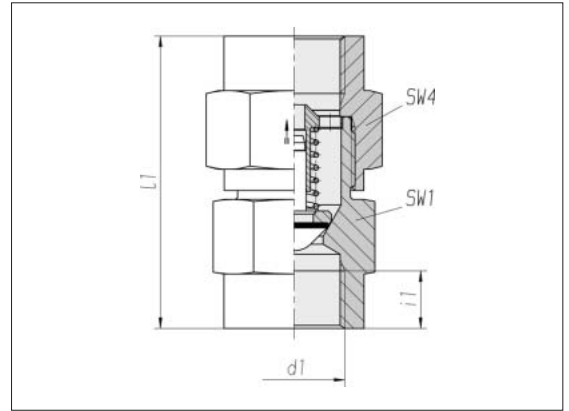

Reihe Rohr-AD	Druck*	d1	SW1	SW4	l1	i1	kg/100 ca.	Bestell-Nr.
L 6	PB 250	G 1/8 A	19	19	50,5	8	10,4	0 6 70 25 20 00**
L 6	PB 250	G 1/4 A	19	19	55	12	11,7	0 6 70 26 20 00
L 10	PB 250	G 3/8 A	24	27	68,5	12	21,0	0 6 70 27 20 00
L 15	PB 250	G 1/2 A	32	36	74	14	35,5	0 6 70 28 20 00
L 18	PB 160	G 3/4 A	41	46	84	16	80,7	0 6 70 29 20 00
L 22	PB 160	G 1 A	46	50	96,5	18	89,2	0 6 70 30 20 00
L 28	PB 100	G 1 1/4 A	60	60	110	20	189,0	0 6 70 31 20 00
L 35	PB 100	G 1 1/2 A	65	70	119	22	237,6	0 6 70 32 20 00

\* Prüfdruck PP = 1,5facher  
Tabellenwert

\*\* Beispiel Bez. Vergl.:  
RHD11/8