


Raccordi maschi filetto metrico sede 24°

Males 24° metric thread


Außengewinde-Nippel 24° metrisches Gewinde

ISO 12151-2 (ISO 8434-1)

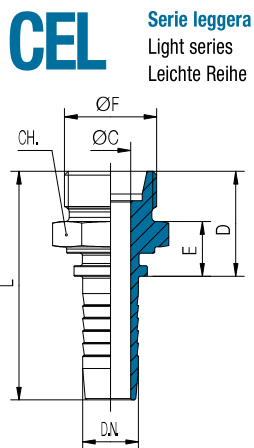

CEL Serie leggera
Light series
Leichte Reihe

CODICE Part n° Bestell-Nr.	DN 24° DN 24° DN 24°	Filetto Thread Gewinde	Ø F ø F ø F	DN Tubo DN Hose DN Schlauch	CH	L	Ø C	D	E
S 30 14 8 906 005	L 6	M 12x1,5	3/16"	05	14	43	3	21	11
S 30 14 8 906 006 A	L 6	M 12x1,5	1/4"	06	14	49	4	21	11
S 30 14 8 908 006	L 8	M 14x1,5	1/4"	06	17	49	4	21	11
S 30 14 8 910 006 A	L 10	M 16x1,5	1/4"	06	17	50	4	22	11
S 30 14 8 910 008	L 10	M 16x1,5	5/16"	08	17	50	5,5	22	11
S 30 14 8 910 010	L 10	M 16x1,5	3/8"	10	17	52,5	7	23	12
S 30 14 8 912 006 A	L 12	M 18x1,5	1/4"	06	19	51	4	23	12
S 30 14 8 912 008 A	L 12	M 18x1,5	5/16"	08	19	51	5,5	23	12
S 30 14 8 912 010	L 12	M 18x1,5	3/8"	10	19	52,5	7	23	12
NEW S 30 14 8 912 013	L 12	M 18x1,5	1/2"	12	22	53,5	9,5	24	13
S 30 14 8 915 010 A	L 15	M 22x1,5	3/8"	10	24	53,5	7	24	12
S 30 14 8 915 013 A	L 15	M 22x1,5	1/2"	12	24	54,5	9,5	25	13
NEW S 30 14 8 915 016	L 15	M 22x1,5	5/8"	16	24	59	12,5	25	13
NEW S 30 14 8 918 010	L 18	M 26x1,5	3/8"	10	27	54,5	7	25	13
S 30 14 8 918 013 A	L 18	M 26x1,5	1/2"	12	27	55,5	9,5	26	14
S 30 14 8 918 016 A	L 18	M 26x1,5	5/8"	16	27	60	12,5	26	14
NEW S 30 14 8 918 019	L 18	M 26x1,5	3/4"	19	27	66,5	15	27,5	15,5
NEW S 30 14 8 922 016	L 22	M 30x2	5/8"	16	32	62	12,5	28	14
S 30 14 8 922 019 A	L 22	M 30x2	3/4"	19	32	68,5	15	29,5	15,5
S 30 14 8 928 025 A	L 28	M 36x2	1"	25	41	77,5	19,5	30,5	16,5
S 30 14 8 935 032 A	L 35	M 45x2	1 1/4"	31	46	91	26	36,5	20,5
S 30 14 8 942 038 A	L 42	M 52x2	1 1/2"	38	55	95,5	32	37,5	21,5

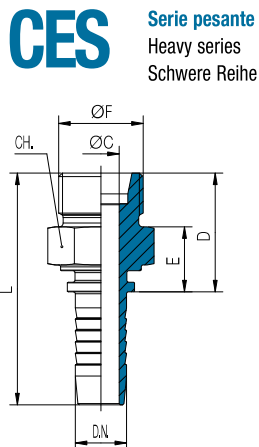

CES Serie pesante
Heavy series
Schwere Reihe

NEW S 30 14 9 906 006	S 6	M 14x1,5	1/4"	06	17	54	4	26	14
NEW S 30 14 9 908 006 A	S 8	M 16x1,5	1/4"	06	17	54	4	26	14
S 30 14 9 908 008	S 8	M 16x1,5	5/16"	08	17	54	5,5	26	14
S 30 14 9 910 006	S 10	M 18x1,5	1/4"	06	19	54	4	26	14
S 30 14 9 910 008 A	S 10	M 18x1,5	5/16"	08	19	54	5,5	26	14
S 30 14 9 910 010 A	S 10	M 18x1,5	3/8"	10	19	55,5	7	26	14
NEW S 30 14 9 912 006	S 12	M 20x1,5	1/4"	06	22	56	4	28	16
S 30 14 9 912 008	S 12	M 20x1,5	5/16"	08	22	56	5,5	28	16
S 30 14 9 912 010	S 12	M 20x1,5	3/8"	10	22	57,5	7	28	16
S 30 14 9 914 010	S 14	M 22x1,5	3/8"	10	24	59,5	7	30	16
S 30 14 9 916 013 A	S 16	M 24x1,5	1/2"	12	27	60,5	9,5	31	17
S 30 14 9 920 016 A	S 20	M 30x2	5/8"	16	32	69	12,5	35	19
S 30 14 9 920 019 A	S 20	M 30x2	3/4"	19	32	75,5	15	36,5	20,5
S 30 14 9 925 019 A	S 25	M 36x2	3/4"	19	36	79,5	15	40,5	22,5
S 30 14 9 925 025 A	S 25	M 36x2	1"	25	36	87,5	19,5	40,5	22,5
S 30 14 9 930 025 A	S 30	M 42x2	1"	25	46	89,5	19,5	42,5	22,5
S 30 14 9 938 032 A	S 38	M 52x2	1 1/4"	31	55	104	26	49,5	27,5