


## 堵头

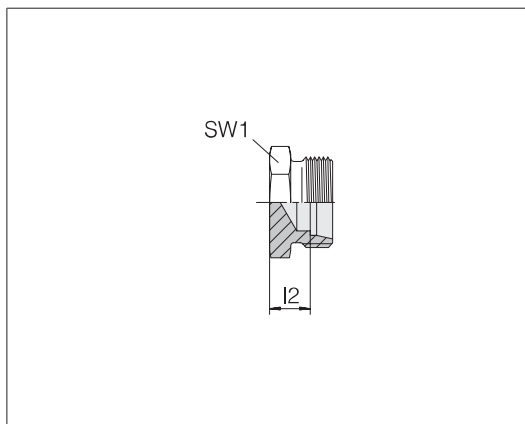

3

管外经系列	压力	l2	SW1	kg/100 大约	订货号	名称
L 6	PN 315	7	12	0.8	0793342000	24-TBS-L6
L 8	PN 315	8	14	1.2	0793352000	24-TBS-L8
L 10	PN 315	9	17	1.6	0793362000	24-TBS-L10
L 12	PN 315	10	19	2.2	0793372000	24-TBS-L12
L 15	PN 315	11	24	3.8	0793382000	24-TBS-L15
L 18	PN 315	11.5	27	5.4	0793392000	24-TBS-L18
L 22	PN 160	13.5	32	7.7	0793402000	24-TBS-L22
L 28	PN 160	14.5	41	13.3	0793412000	24-TBS-L28
L 35	PN 160	14.5	46	20.1	0793422000	24-TBS-L35
L 42	PN 160	16	55	34.0	0793432000	24-TBS-L42
S 6	PN 630	11	14	1.6	0793442000	24-TBS-S6
S 8	PN 630	13	17	2.6	0793452000	24-TBS-S8
S 10	PN 630	12.5	19	3.1	0793462000	24-TBS-S10
S 12	PN 630	14.5	22	4.5	0793472000	24-TBS-S12
S 14	PN 630	16	24	5.9	0793482000	24-TBS-S14
S 16	PN 400	15.5	27	6.8	0793492000	24-TBS-S16
S 20	PN 400	17.5	32	12.0	0793502000	24-TBS-S20
S 25	PN 400	20	41	21.3	0793512000	24-TBS-S25
S 30	PN 400	20.5	46	28.1	0793522000	24-TBS-S30
S 38	PN 315	23	55	49.8	0793532000	24-TBS-S38

相关比较示例：  
ROV06LX