


## 24/37°支撑套管

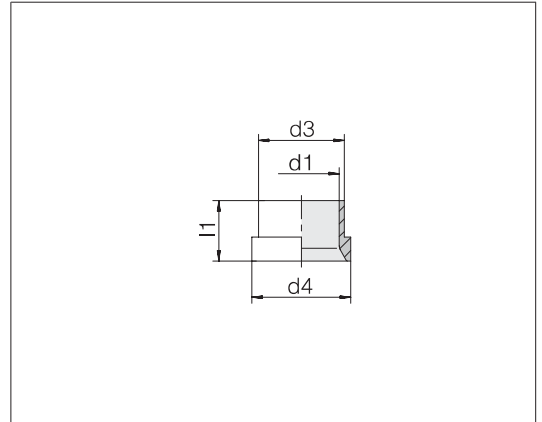

3

系列管外径 d1	压力	d3	d4	l1	kg/100 大约	订货号	名称
L/S 6	PN 500/630	7.6	10.2	10.5	0.2	0041202000	24-24/37R-L/S6
L/S 8	PN 500/630	9.3	12.2	11	0.3	0041212000	24-24/37R-L/S8
L/S 10	PN 500/630	11.5	14.2	12.5	0.4	0041222000	24-24/37R-L/S10
L/S 12	PN 400/630	13.6	16.2	13	0.5	0041232000	24-24/37R-L/S12
L 15	PN 400	17.5	20.2	14	1.0	0041242000	24-24/37R-L15
L 18	PN 400	21	24.2	14.5	1.5	0041252000	24-24/37R-L18
L 22	PN 250	24.2	27.8	18	1.7	0041262000	24-24/37R-L22
L 28	PN 250	30.2	33.8	17	2.0	0041272000	24-24/37R-L28
L 35	PN 250	38	42.7	19	3.8	0041282000	24-24/37R-L35
L 42	PN 250	45	49.7	21	5.2	0041292000	24-24/37R-L42
S 14	PN 630	17.5	20.2	14.5	1.2	0041302000	24-24/37R-S14
S 16	PN 630	18.5	22	17	1.3	0041312000	24-24/37R-S16
S 20	PN 400	24.2	27.8	17.5	2.5	0041322000	24-24/37R-S20
S 25	PN 400	28.5	32.8	20	3.2	0041332000	24-24/37R-S25
S 30	PN 400	34	39	21.5	4.9	0041342000	24-24/37R-S30
S 38	PN 400	42	48.5	26.5	7.7	0041352000	24-24/37R-S38