


Swivel unions

Directionally adjustable taper coupling on both sides

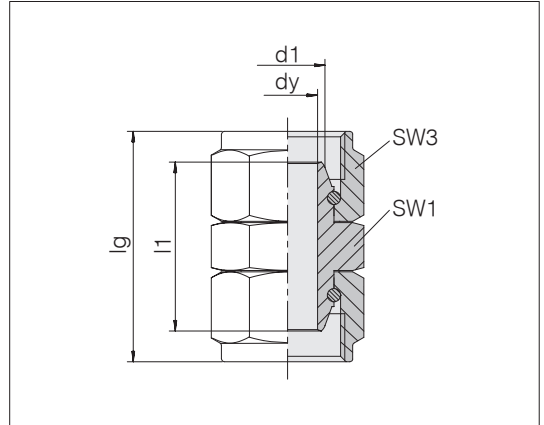

Tube OD d1	dy	lg	l1	SW1	SW3	kg/100 ca.	Order-No.	Designation
6	4.5	36	25.6	12	14	2.9	7000919500	40-SW2S-6-SST
8	6.5	35.8	25.6	14	16	3.8	7000919600	40-SW2S-8-SST
10	8	37.6	27	17	19	5.2	7000919700	40-SW2S-10-SST
12	9.5	41.2	29.8	19	22	7.1	7000919800	40-SW2S-12-SST
14	11.5	41	29.8	22	25	8.9	7000919900	40-SW2S-14-SST
15	12	41	30	22	25	9.0	7000920000	40-SW2S-15-SST
16	13	40.6	30	22	25	8.7	7000920100	40-SW2S-16-SST
18	15	43.8	32.4	24	30	13.6	7000920200	40-SW2S-18-SST
20	16	44.6	33.4	27	32	15.0	7000920300	40-SW2S-20-SST
22	18	44	33.4	27	32	14.2	7000920400	40-SW2S-22-SST