


## 2SVA cutting rings

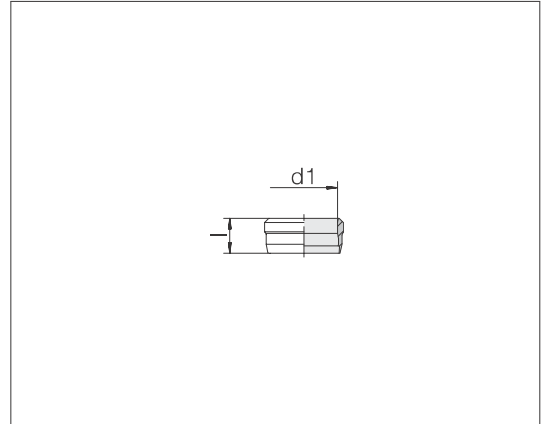

Series Tube OD d1	Pressure	l	Order-No.	Designation
L/S 6	PN 315/630	8.8	0010006200	24-2S-L/S6-SST-C62
L/S 8	PN 315/630	8.8	0010056200	24-2S-L/S8-SST-C62
L/S 10	PN 315/630	9.8	0010106200	24-2S-L/S10-SST-C62
L/S 12	PN 315/630	9.8	0010156200	24-2S-L/S12-SST-C62
L 15	PN 315	10.2	0010206200	24-2S-L15-SST-C62
L 18	PN 315	10.2	0010256200	24-2S-L18-SST-C62
L 22	PN 160	11.5	0010306200	24-2S-L22-SST-C62
L 28	PN 160	11.5	0010356200	24-2S-L28-SST-C62
L 35	PN 160	13.5	0010406200	24-2S-L35-SST-C62
L 42	PN 160	13.5	0010456200	24-2S-L42-SST-C62
S 14	PN 630	10.2	0010706200	24-2S-S14-SST-C62
S 16	PN 400	10.2	0010756200	24-2S-S16-SST-C62
S 20	PN 400	12.5	0010806200	24-2S-S20-SST-C62
S 25	PN 400	12.5	0010856200	24-2S-S25-SST-C62
S 30	PN 400	13.5	0010906200	24-2S-S30-SST-C62
S 38	PN 315	13.5	0010956200	24-2S-S38-SST-C62

Cutting-rings for tube OD  
6 - 12 mm are identical for  
series L + S .

Example for comp. :  
DPR06L71X