


24/37° flared connecting parts

Standard O-ring material is FPM/FKM

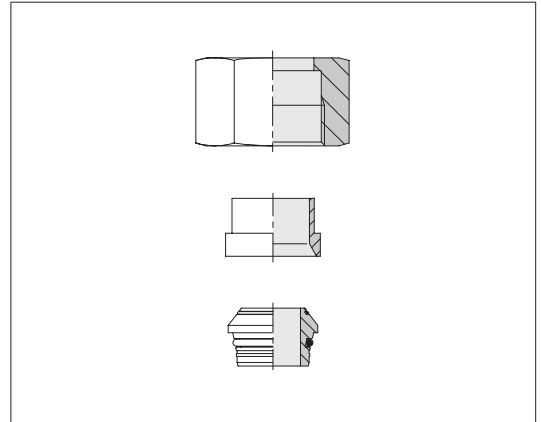

3

Series Tube OD	Pressure	kg/100 ca.	Order-No.	Designation
L 6	PN 500	1.7	0041602058	24-24/37SO-L6
L 8	PN 500	2.6	0041612058	24-24/37SO-L8
L 10	PN 500	3.4	0041622058	24-24/37SO-L10
L 12	PN 400	4.8	0041632058	24-24/37SO-L12
L 15	PN 400	7.7	0041642058	24-24/37SO-L15
L 18	PN 400	10.7	0041652058	24-24/37SO-L18
L 22	PN 250	15.3	0041662058	24-24/37SO-L22
L 28	PN 250	17.4	0041672058	24-24/37SO-L28
L 35	PN 250	27.8	0041682058	24-24/37SO-L35
L 42	PN 250	45.7	0041692058	24-24/37SO-L42
S 6	PN 630	2.5	0041702058	24-24/37SO-S6
S 8	PN 630	3.1	0041712058	24-24/37SO-S8
S 10	PN 630	4.6	0041722058	24-24/37SO-S10
S 12	PN 630	5.4	0041732058	24-24/37SO-S12
S 14	PN 630	8.1	0041742058	24-24/37SO-S14
S 16	PN 630	11.2	0041752058	24-24/37SO-S16
S 20	PN 400	16.8	0041762058	24-24/37SO-S20
S 25	PN 400	30.3	0041772058	24-24/37SO-S25
S 30	PN 400	35.0	0041782058	24-24/37SO-S30
S 38	PN 400	54.0	0041792058	24-24/37SO-S38