
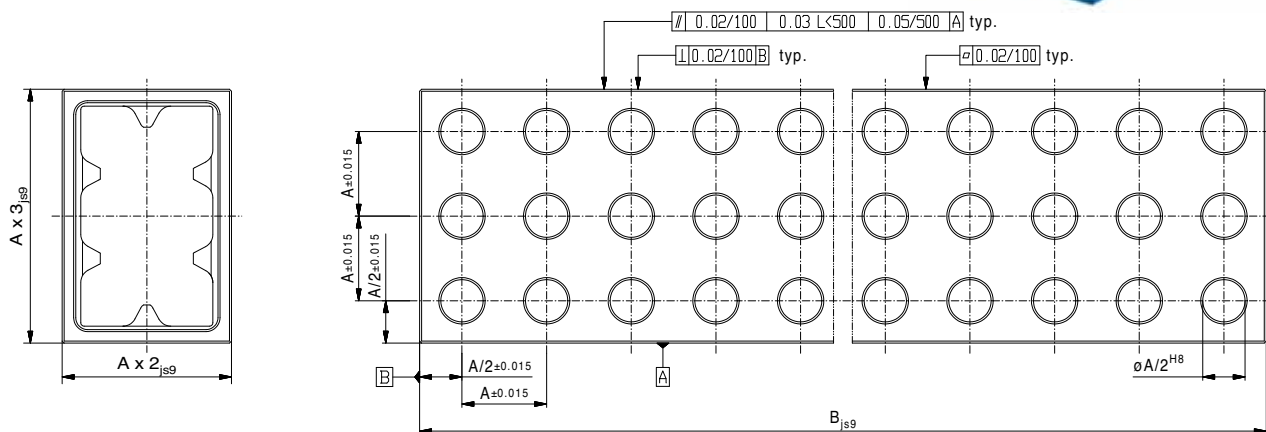


Light bars rectangular

ALUFIX ECO Light bars are suitable for medium to large fixtures as basic frame material and also for connections direct to the workpiece.

They can be connected using the bores on all 4 sides with quick

or screw connectors, ECO couplings (page 196/197) are used for the face ends.

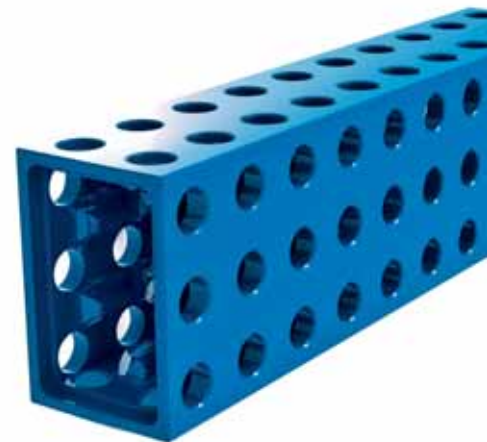

AF25 ECO A=25, 25 x 50

Nr.	B	g
122567-E	100	230
122568-E	200	460
122569-E	300	690
122570-E	400	920
122571-E	500	1.150
122572-E	600	1.380
122573-E	800	1.840
122574-E	1000	2.300
122575-E	1200	2.760
122576-E	1500	3.450
122577-E	2000	7.000

AF40 ECO A=40, 40 x 80

Nr.	B	g
122285-E	160	1.000
122286-E	200	1.250
122287-E	240	1.500
122289-E	320	2.000
122290-E	360	2.250
122291-E	400	2.500
122296-E	600	3.750
122301-E	800	5.000
122306-E	1000	6.250
122311-E	1200	7.500
122321-E	1600	10.000
122331-E	2000	12.500
122341-E	2400	15.000
122354-E	3000	18.750
122369-E	3600	22.500
122379-E	4000	25.000
122578-E	4800	30.000



Blind Covers for ALUFIX ECO bars see page 29