


Grid base plates ALUFIX ECO

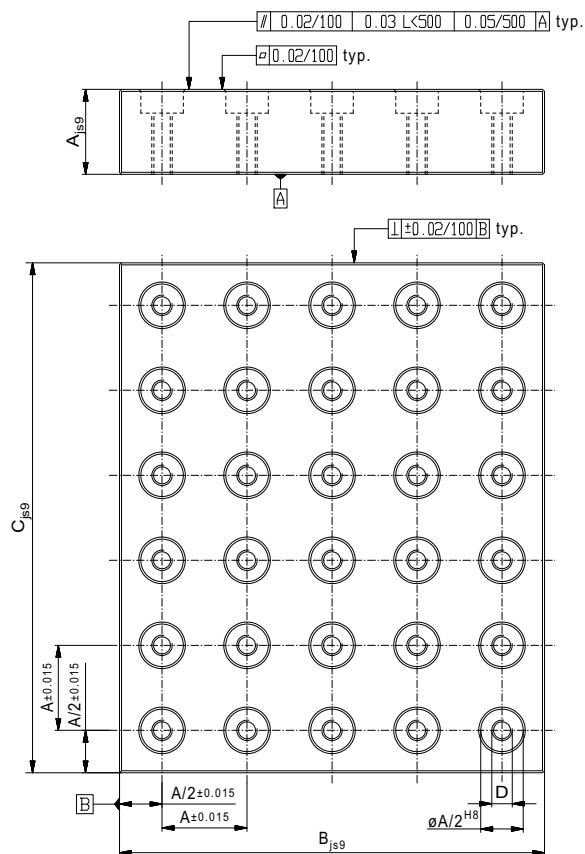

Grid base plates

AF25 ECO,
A=25, D=M6

Nr.	A x B x C	g
20387-E	25 x 200 x 400	5.500
20388-E	25 x 250 x 500	8.600
20403-E	25 x 300 x 400	8.400
20386-E	25 x 300 x 600	12.400
22923-E	25 x 400 x 500	13.300
22925-E	25 x 400 x 600	16.800
20439-E	25 x 500 x 500	17.500
20381-E	25 x 500 x 1000	34.400
20382-E	25 x 600 x 600	24.800
20384-E	25 x 600 x 800	33.000

AF40 ECO,
A=40, D=M10

Nr.	A x B x C	g
20650-E	40 x 320 x 640	22.600
20651-E	40 x 400 x 800	35.300
20710-E	40 x 480 x 640	33.900
20711-E	40 x 480 x 960	50.800
20713-E	40 x 640 x 800	56.400
20714-E	40 x 640 x 960	67.600
20715-E	40 x 800 x 800	70.400
20808-E	40 x 800 x 1600	140.000
20809-E	40 x 960 x 960	101.200
20810-E	40 x 960 x 1280	135.000

AF50 ECO,
A=50, D=M12

Nr.	A x B x C	g
28083-E	50 x 400 x 400	22.000
28084-E	50 x 500 x 1000	69.000
28085-E	50 x 600 x 800	66.000
28086-E	50 x 600 x 1200	100.000
28087-E	50 x 800 x 1000	110.000
28088-E	50 x 800 x 1200	138.000
28089-E	50 x 1000 x 1000	133.000
28090-E	50 x 1000 x 2000	276.000
28091-E	50 x 1200 x 1200	198.000
28092-E	50 x 1200 x 1600	248.000



ALUFIX ECO elements can be anodized in different colours. The colour natural (-E) is standard, blue (-E2) is available as an alternative. Black (-E1) and other colours on request

