


## Guiding slide with slide stop

movement assisted by free floating rollers

Nr.	A (AF)	B	shift	A/min	A/max	max. load	
82015	16	7	± 8,5	59	77	20 kg	70
82002	25	10,5	± 13,5	93	120,5	50 kg	250
82016	40	16,8	± 22	146,8	192	150 kg	1.024
82441	50	21	± 27,5	186	242	250 kg	6.000

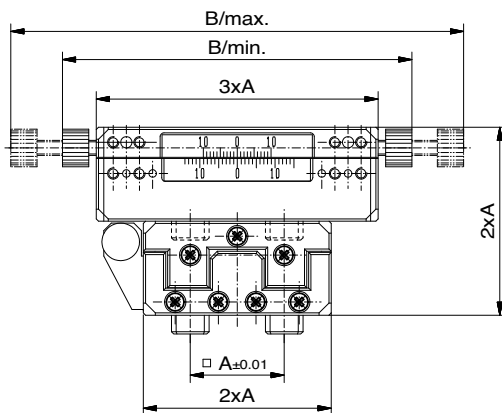

## Cross guiding slide with slide stop

movement assisted by free floating rollers

Nr.	A (AF)	B/min	B/max	max. load	shift	
82436	16	59	77	20 kg	± 8,5	150
82437	25	93	120,5	50 kg	± 13,5	520
82438	40	146,8	192	150 kg	± 22	2.100
82439	50	186	242	250 kg	± 27,5	12.500

